

Direct acting solenoid valves - Series PD

Product code: PD000-2A2-F52-OX2

Datasheet creation date: 20/05/2026 04:06

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	PD
Body execution	0 = single body
Number of seats	00 = interface
Number of ways - Functions	2 = 2/2 way - NC
Material - Body connections	A = aluminum body - side interface
Orifice diameter	2 = Ø 1.2 mm
kv (l/min)	0.54
Seal material	F = FKM
Electrical connection	5 = industry standard (9.4 mm)
Voltage - Absorbed power	2 = 12 V DC - 2 W
Fixing	= fixing screws for metal or clips for sub-base
Use with oxygen	OX2 = for use with oxygen – cleanliness level according to ASTM G93-03 Standard Level B

Direct acting solenoid valves - Series PD

Product code: PD000-2A2-F52-OX2

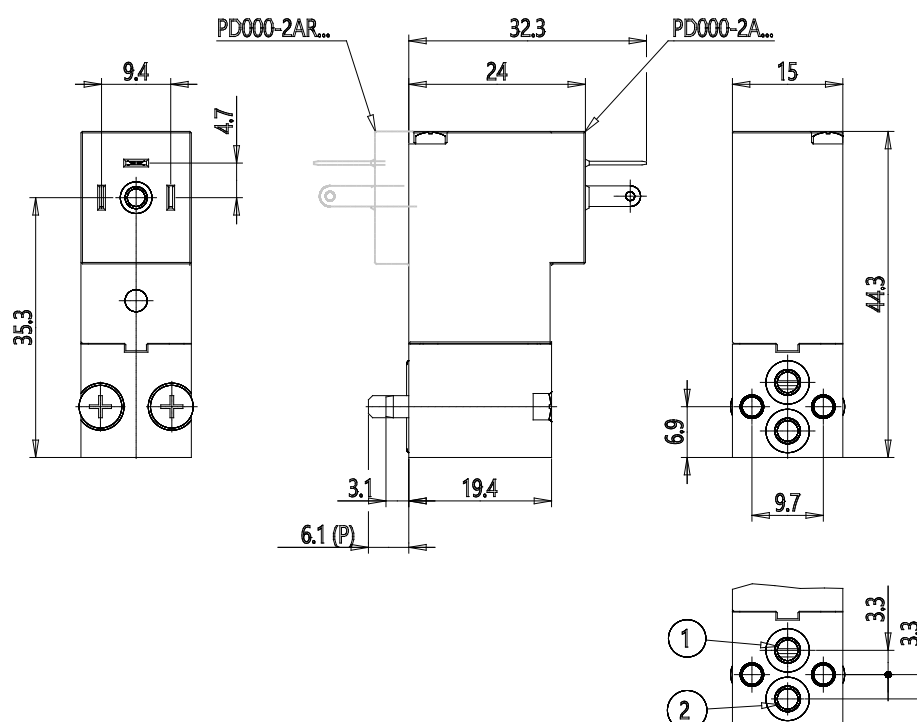

DIMENSIONS

Series	PD
Body execution	0 = single body
Number of seats	00 = interface
Number of ways - Functions	2 = 2/2 way - NC
Material - Body connections	A = aluminum body - side interface
Orifice diameter	2 = Ø 1.2 mm
kv (l/min)	0.54
Seal material	F = FKM
Electrical connection	5 = industry standard (9.4 mm)
Voltage - Absorbed power	2 = 12 V DC - 2 W
Fixing	= fixing screws for metal or clips for sub-base
Use with oxygen	OX2 = for use with oxygen – cleanliness level according to ASTM G93-03 Standard Level B