

Direct acting solenoid valves - Series PD

Product code: PD000-2A3-E52

Datasheet creation date: 20/05/2026 04:48

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	PD
Body execution	0 = single body
Number of seats	00 = interface
Number of ways - Functions	2 = 2/2 way - NC
Material - Body connections	A = aluminum body - side interface
Orifice diameter	3 = Ø 1.6 mm
kv (l/min)	0.70
Seal material	E = EPDM
Electrical connection	5 = industry standard (9.4 mm)
Voltage - Absorbed power	2 = 12 V DC - 2 W
Fixing	= fixing screws for metal or clips for sub-base
Use with oxygen	= Not suitable for use with oxygen

Direct acting solenoid valves - Series PD

Product code: PD000-2A3-E52

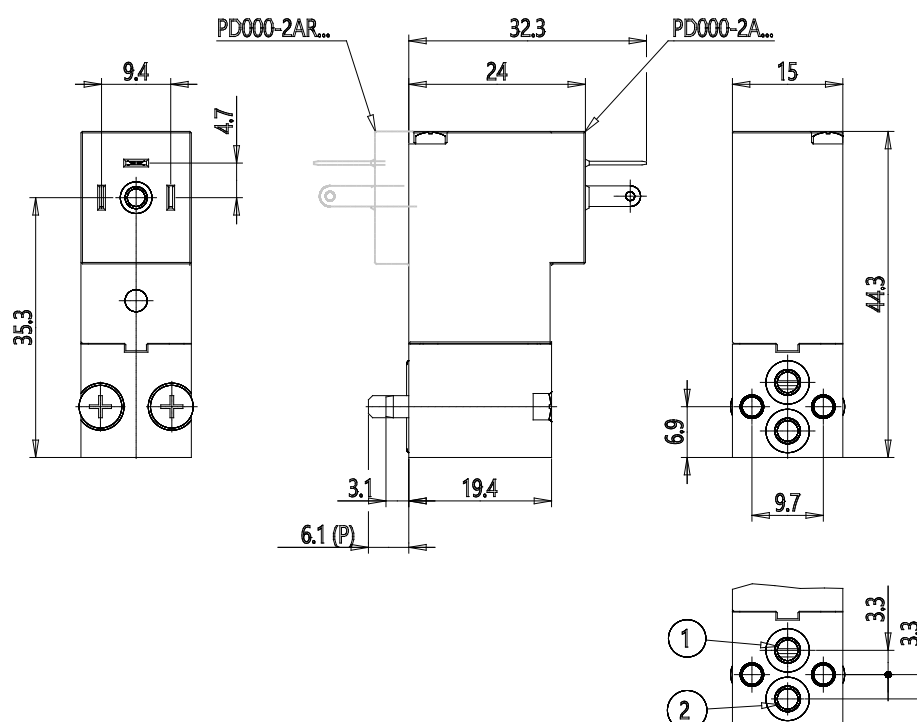

DIMENSIONS

Series	PD
Body execution	0 = single body
Number of seats	00 = interface
Number of ways - Functions	2 = 2/2 way - NC
Material - Body connections	A = aluminum body - side interface
Orifice diameter	3 = \varnothing 1.6 mm
kv (l/min)	0.70
Seal material	E = EPDM
Electrical connection	5 = industry standard (9.4 mm)
Voltage - Absorbed power	2 = 12 V DC - 2 W
Fixing	= fixing screws for metal or clips for sub-base
Use with oxygen	= Not suitable for use with oxygen