

Direct Operated Solenoid Valves with Separation Diaphragm - PDV Series

Product code: PDVC0122-A73GN-M003AC023

Datasheet creation date: 10/03/2025 11:39

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	PDV
Body execution	C0 = body with interface for subbase
Number of ways - functions	1 = 2/2 way - NC
Pneumatic connections	22 = PDV-type interface, 2-way
Orifice diameter	A7 = \varnothing 0.8 mm
Materials held	3 = FKM
Body materials	G = PEEK
Manual intervention	N = not foreseen
Fixing	M = fixing screws for metal
Options	00 = none
Electrical connection	3A = DIN EN 175 301-803-C (8 mm)
Voltage - absorbed power	C023 = 24 V DC - 2 W

Direct Operated Solenoid Valves with Separation Diaphragm - PDV Series

Product code: PDVC0122-A73GN-M003AC023

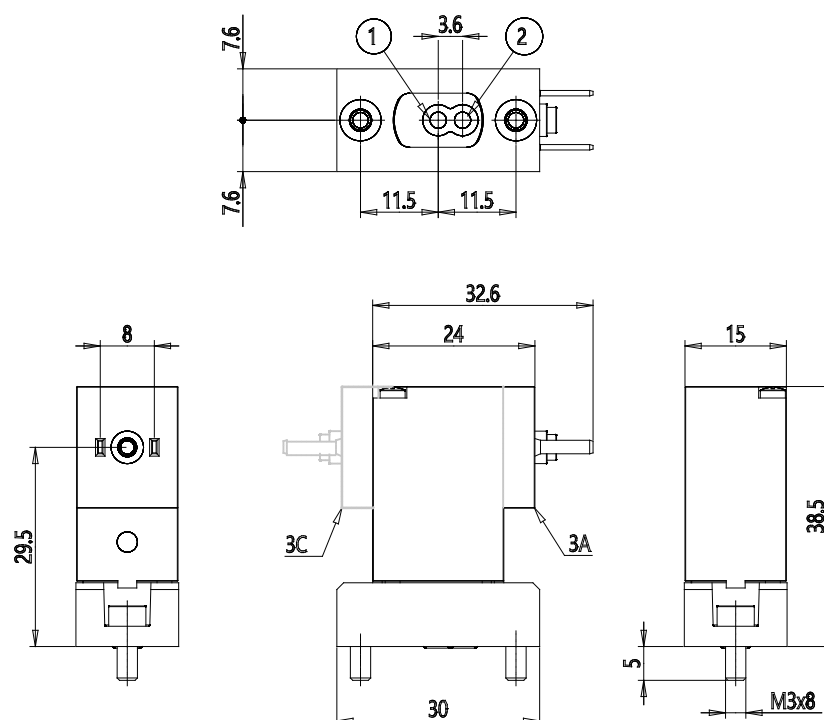

DIMENSIONS

Series	PDV
Body execution	C0 = body with interface for subbase
Number of ways - functions	1 = 2/2 way - NC
Pneumatic connections	22 = PDV-type interface, 2-way
Orifice diameter	A7 = \varnothing 0.8 mm
Materials held	3 = FKM
Body materials	G = PEEK
Manual intervention	N = not foreseen
Fixing	M = fixing screws for metal
Options	00 = none
Electrical connection	3A = DIN EN 175 301-803-C (8 mm)
Voltage - absorbed power	C023 = 24 V DC - 2 W