

Direct Operated Solenoid Valves with Separation Diaphragm - PDV Series

Product code: PDVC0122-C15GN-M007AC023

Datasheet creation date: 10/03/2025 11:41

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	PDV
Body execution	C0 = body with interface for subbase
Number of ways - functions	1 = 2/2 way - NC
Pneumatic connections	22 = PDV-type interface, 2-way
Orifice diameter	C1 = Ø 2.0 mm
Materials held	5 = FFKM
Body materials	G = PEEK
Manual intervention	N = not foreseen
Fixing	M = fixing screws for metal
Options	00 = none
Electrical connection	7A = cables 300 mm
Voltage - absorbed power	C023 = 24 V DC - 2 W

Direct Operated Solenoid Valves with Separation Diaphragm - PDV Series

Product code: PDVC0122-C15GN-M007AC023

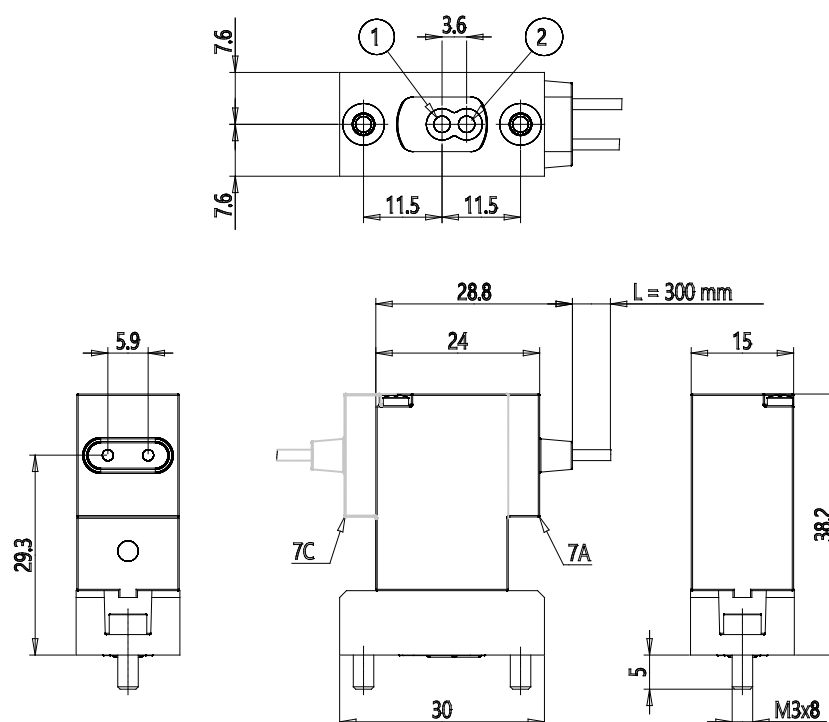

DIMENSIONS

Series	PDV
Body execution	C0 = body with interface for subbase
Number of ways - functions	1 = 2/2 way - NC
Pneumatic connections	22 = PDV-type interface, 2-way
Orifice diameter	C1 = Ø 2.0 mm
Materials held	5 = FFKM
Body materials	G = PEEK
Manual intervention	N = not foreseen
Fixing	M = fixing screws for metal
Options	00 = none
Electrical connection	7A = cables 300 mm
Voltage - absorbed power	C023 = 24 V DC - 2 W