

Direct acting solenoid valves - Series PL

Product code: PL000-30B-PF26P

Datasheet creation date: 20/05/2026 06:48

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	PL
Valvebody	0 = interface
Number of positions	00 = without subbase/conveyors
Number of ways - Functions	3 = 3/2 way - NC
Valve connections	0 = single sub-base (M5 only) or interface
Orifice diametres	B = Ø 0.8 mm
Materials	PF = PBT body - FKM seals
Electric connection	2 = industrial standard connection (9.4 mm)
Voltage - Absorbed power	6 = 24 V DC - 1.2 W - PA
Fixing	P = fixing screws for plastic
Manual override	= not required or not applicable
Use with oxygen	= Not suitable for use with oxygen

Direct acting solenoid valves - Series PL

Product code: PL000-30B-PF26P

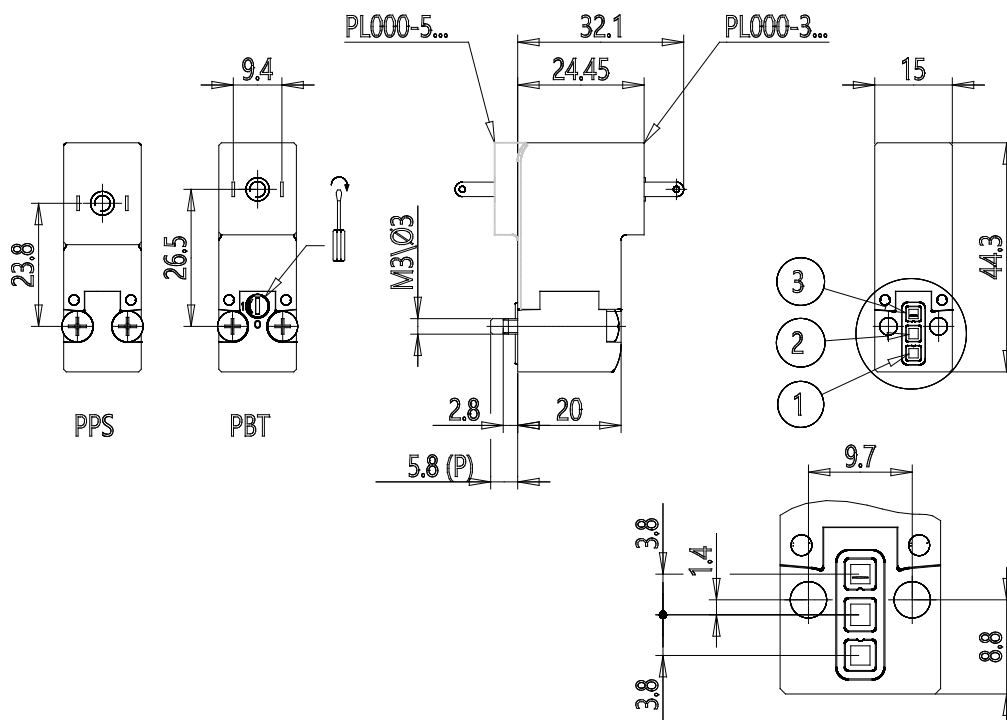

DIMENSIONS

Series	PL
Valvebody	0 = interface
Number of positions	00 = without subbase/conveyors
Number of ways - Functions	3 = 3/2 way - NC
Valve connections	0 = single sub-base (M5 only) or interface
Orifice diametres	B = Ø 0.8 mm
Materials	PF = PBT body - FKM seals
Electric connection	2 = industrial standard connection (9.4 mm)
Voltage - Absorbed power	6 = 24 V DC - 1.2 W - PA
Fixing	P = fixing screws for plastic
Manual override	= not required or not applicable
Use with oxygen	= Not suitable for use with oxygen