

Direct acting solenoid valves - Series PL

Product code: PL000-30B-ST2H

Datasheet creation date: 10/03/2025 11:41

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	PL
Valvebody	0 = interface
Number of positions	00 = ISO 15218 or Series PD interface
Number of ways - Functions	3 = 3/2 way - NC
Valve connections	0 = single sub-base (M5 only) or interface
Orifice diametres	B = Ø 0.8 mm
Materials	ST = PPS body - Low Temperature NBR seals (on demand)
Electric connection	2 = industrial standard connection (9.4 mm)
Voltage - Absorbed power	H = 110 V DC - 3 W - PPS (can be combined with all PPS models)
Fixing	= fixing screws for metal
Manual override	= not required or not applicable
Option	= standard

Direct acting solenoid valves - Series PL

Product code: PL000-30B-ST2H

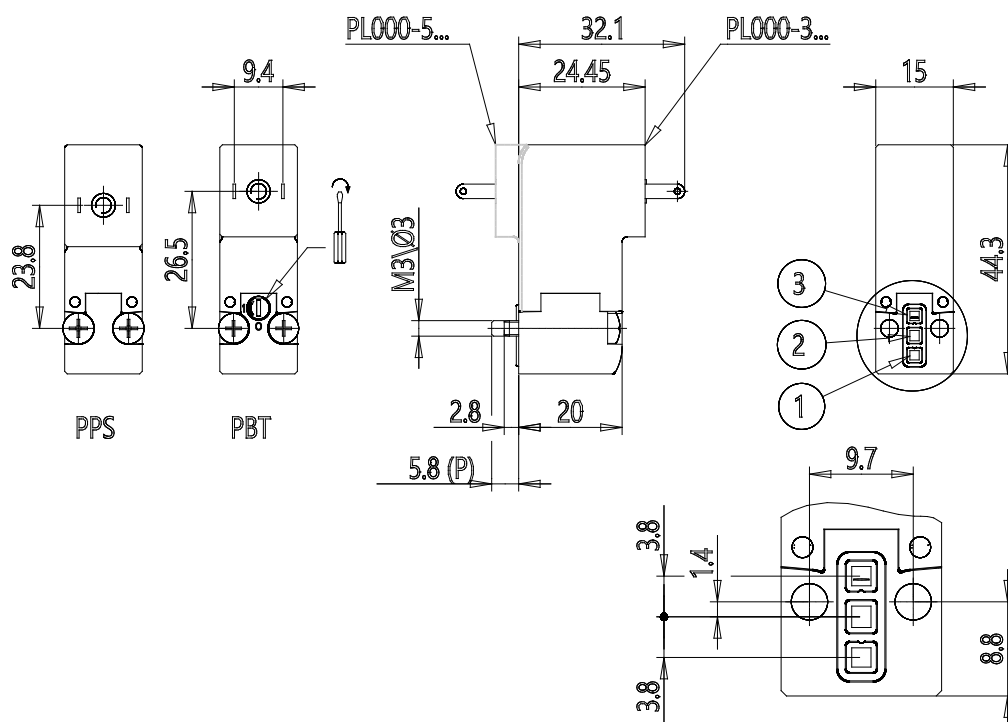

DIMENSIONS

Series	PL
Valvebody	0 = interface
Number of positions	00 = ISO 15218 or Series PD interface
Number of ways - Functions	3 = 3/2 way - NC
Valve connections	0 = single sub-base (M5 only) or interface
Orifice diametres	B = \varnothing 0.8 mm
Materials	ST = PPS body - Low Temperature NBR seals (on demand)
Electric connection	2 = industrial standard connection (9.4 mm)
Voltage - Absorbed power	H = 110 V DC - 3 W - PPS (can be combined with all PPS models)
Fixing	= fixing screws for metal
Manual override	= not required or not applicable
Option	= standard