

Direct acting solenoid valves - Series PL

Product code: PL000-401-ST2C

Datasheet creation date: 10/03/2025 11:41

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	PL
Valvebody	0 = interface
Number of positions	00 = ISO 15218 or Series PD interface
Number of ways - Functions	4 = 3/2 vie - NO
Valve connections	0 = single sub-base (M5 only) or interface
Orifice diametres	1 = Ø 1.1 mm
Materials	ST = PPS body - Low Temperature NBR seals (on demand)
Electric connection	2 = industrial standard connection (9.4 mm)
Voltage - Absorbed power	C = 24 V DC - 2.2 W - PPS
Fixing	= fixing screws for metal
Manual override	= not required or not applicable
Option	= standard

Direct acting solenoid valves - Series PL

Product code: PL000-401-ST2C

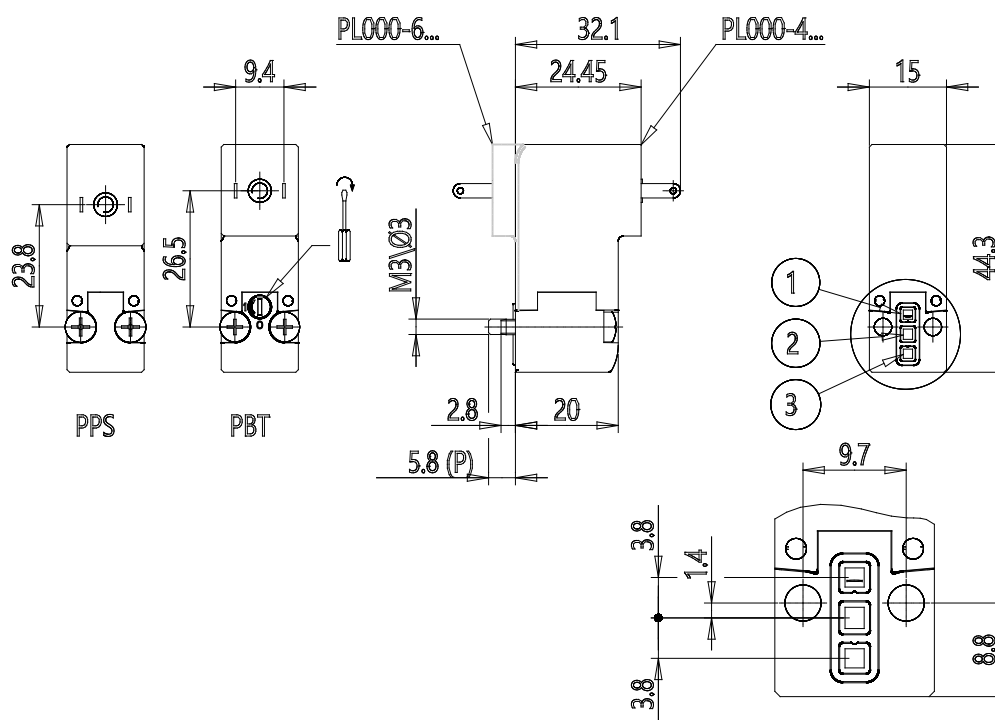

DIMENSIONS

Series	PL
Valvebody	0 = interface
Number of positions	00 = ISO 15218 or Series PD interface
Number of ways - Functions	4 = 3/2 vie - NO
Valve connections	0 = single sub-base (M5 only) or interface
Orifice diametres	1 = Ø 1.1 mm
Materials	ST = PPS body - Low Temperature NBR seals (on demand)
Electric connection	2 = industrial standard connection (9.4 mm)
Voltage - Absorbed power	C = 24 V DC - 2.2 W - PPS
Fixing	= fixing screws for metal
Manual override	= not required or not applicable
Option	= standard