

Direct acting solenoid valves - Series PL

Product code: PL000-405-PF23

Datasheet creation date: 10/03/2025 11:41

Check the most updated document online [click here](#)




TECHNICAL DATA

| | |
|-----------------------------------|---|
| Series | PL |
| Valvebody | 0 = interface |
| Number of positions | 00 = ISO 15218 or Series PD interface |
| Number of ways - Functions | 4 = 3/2 vie - NO |
| Valve connections | 0 = single sub-base (M5 only) or interface |
| Orifice diametres | 5 = Ø 1.5 mm |
| Materials | PF = PBT body - FKM seals |
| Electric connection | 2 = industrial standard connection (9.4 mm) |
| Voltage - Absorbed power | 3 = 24 V DC - 2.7 W - PA |
| Fixing | = fixing screws for metal |
| Manual override | = not required or not applicable |
| Option | = standard |

Direct acting solenoid valves - Series PL

Product code: PL000-405-PF23

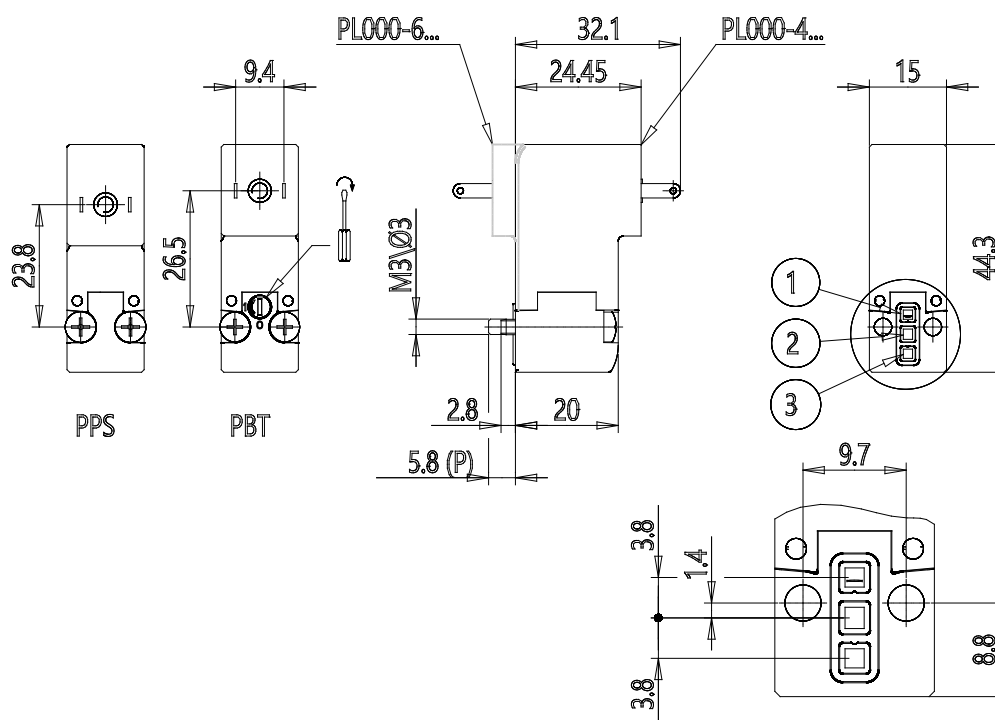

DIMENSIONS

| | |
|-----------------------------------|---|
| Series | PL |
| Valvebody | 0 = interface |
| Number of positions | 00 = ISO 15218 or Series PD interface |
| Number of ways - Functions | 4 = 3/2 vie - NO |
| Valve connections | 0 = single sub-base (M5 only) or interface |
| Orifice diametres | 5 = Ø 1.5 mm |
| Materials | PF = PBT body - FKM seals |
| Electric connection | 2 = industrial standard connection (9.4 mm) |
| Voltage - Absorbed power | 3 = 24 V DC - 2.7 W - PA |
| Fixing | = fixing screws for metal |
| Manual override | = not required or not applicable |
| Option | = standard |