

Direct acting solenoid valves - Series PL

Product code: PL000-50B-PF26

Datasheet creation date: 10/03/2025 11:42

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	PL
Valvebody	0 = interface
Number of positions	00 = ISO 15218 or Series PD interface
Number of ways - Functions	5 = 3/2 ways - NC electrical part turned by 180 °
Valve connections	0 = single sub-base (M5 only) or interface
Orifice diametres	B = Ø 0.8 mm
Materials	PF = PBT body - FKM seals
Electric connection	2 = industrial standard connection (9.4 mm)
Voltage - Absorbed power	6 = 24 V DC - 1.2 W - PA
Fixing	= fixing screws for metal
Manual override	= not required or not applicable
Option	= standard

Direct acting solenoid valves - Series PL

Product code: PL000-50B-PF26

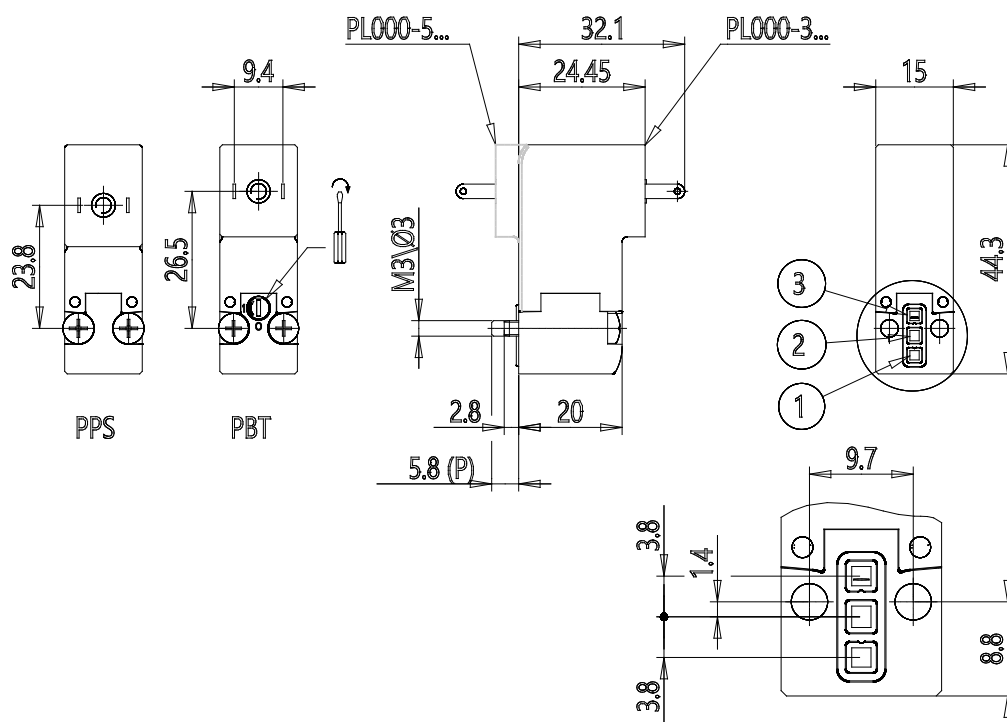

DIMENSIONS

Series	PL
Valvebody	0 = interface
Number of positions	00 = ISO 15218 or Series PD interface
Number of ways - Functions	5 = 3/2 ways - NC electrical part turned by 180 °
Valve connections	0 = single sub-base (M5 only) or interface
Orifice diametres	B = Ø 0.8 mm
Materials	PF = PBT body - FKM seals
Electric connection	2 = industrial standard connection (9.4 mm)
Voltage - Absorbed power	6 = 24 V DC - 1.2 W - PA
Fixing	= fixing screws for metal
Manual override	= not required or not applicable
Option	= standard