

Direct acting solenoid valves - Series PL

Product code: PL000-9B7-PF22

Datasheet creation date: 10/03/2025 11:42

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	PL
Valvebody	0 = interface
Number of positions	00 = ISO 15218 or Series PD interface
Number of ways - Functions	9 = 2/2-way - NO
Valve connections	B = series PD interface - 2/2-way
Orifice diametres	7 = Ø 1.6 mm
Materials	PF = PBT body - FKM seals
Electric connection	2 = industrial standard connection (9.4 mm)
Voltage - Absorbed power	2 = 12 V DC - 2.7 W - PA
Fixing	= fixing screws for metal
Manual override	= not required or not applicable
Option	= standard

Direct acting solenoid valves - Series PL

Product code: PL000-9B7-PF22

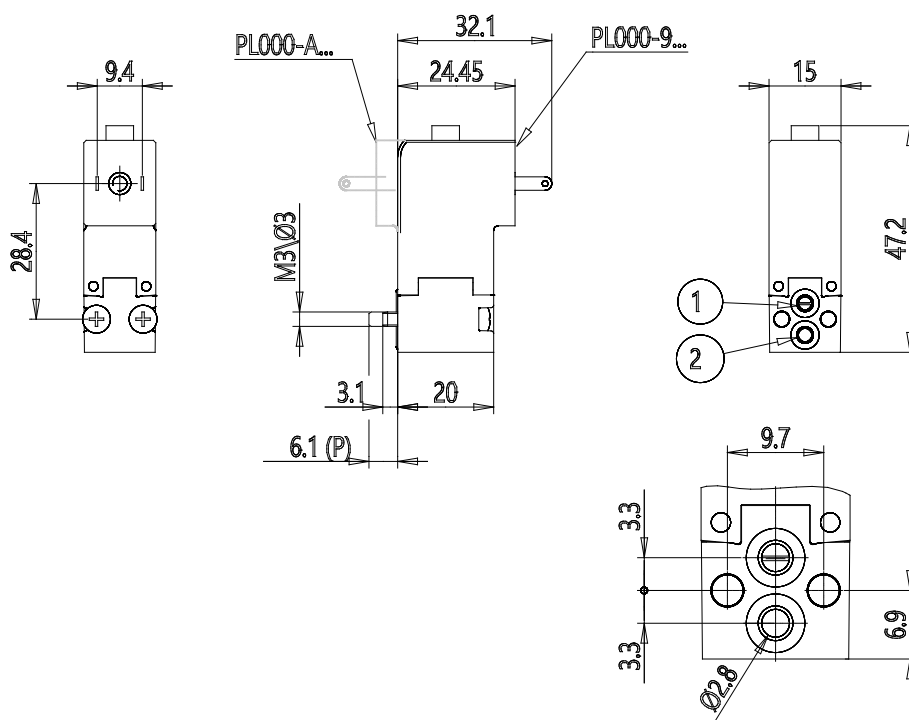

DIMENSIONS

Series	PL
Valvebody	0 = interface
Number of positions	00 = ISO 15218 or Series PD interface
Number of ways - Functions	9 = 2/2-way - NO
Valve connections	B = series PD interface - 2/2-way
Orifice diametres	7 = Ø 1.6 mm
Materials	PF = PBT body - FKM seals
Electric connection	2 = industrial standard connection (9.4 mm)
Voltage - Absorbed power	2 = 12 V DC - 2.7 W - PA
Fixing	= fixing screws for metal
Manual override	= not required or not applicable
Option	= standard