

Electronic proportional regulator - Series PME

Product code: PME104-EG5I4E-5R

Datasheet creation date: 10/03/2025 10:36

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	PME
size	1 = Size 1
Connections	04 = G1/4
Diagnostics	E = Without diagnostics and wireless connection
Pressure	G = 0-7 bar
Function	5 = Standard, 3-way NC version. with port 3 and pilot exhaust not conveyable
Piloting	I = Internal
Command signal	4 = 4-20 mA
Feedback digital output signal	E = Error signal
Cable length	5R = 5mt 90°

Electronic proportional regulator - Series PME

Product code: PME104-EG5I4E-5R

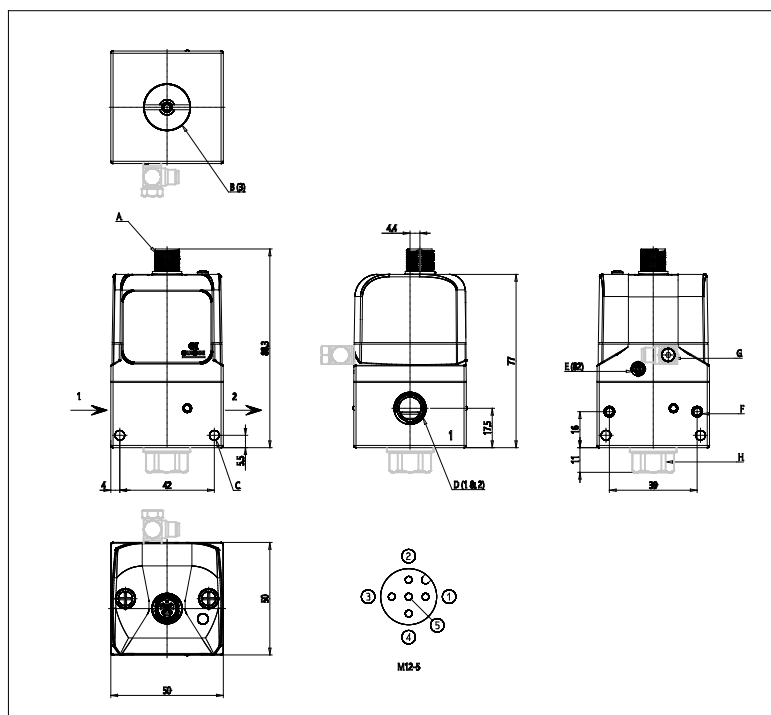

DIMENSIONS

Series	PME
size	1 = Size 1
Connections	04 = G1/4
Diagnostics	E = Without diagnostics and wireless connection
Pressure	G = 0-7 bar
Function	5 = Standard, 3-way NC version. with port 3 and pilot exhaust not conveyable
Piloting	I = Internal
Command signal	4 = 4-20 mA
Feedback digital output signal	E = Error signal
Cable length	5R = 5mt 90°