

Electronic proportional regulator - Series PME

Product code: PME108-ED5I4W-00

Datasheet creation date: 10/03/2025 10:37

Check the most updated document online [click here](#)




TECHNICAL DATA

Series	PME
size	1 = Size 1
Connections	08 = G1/8
Diagnostics	E = Without diagnostics and wireless connection
Pressure	D = 0-10,3 bar
Function	5 = Standard, 3-way NC version. with port 3 and pilot exhaust not conveyable
Piloting	I = Internal
Command signal	4 = 4-20 mA
Feedback digital output signal	W = pressure switch with "window" function
Cable length	00 = No cable

Electronic proportional regulator - Series PME

Product code: PME108-ED5I4W-00

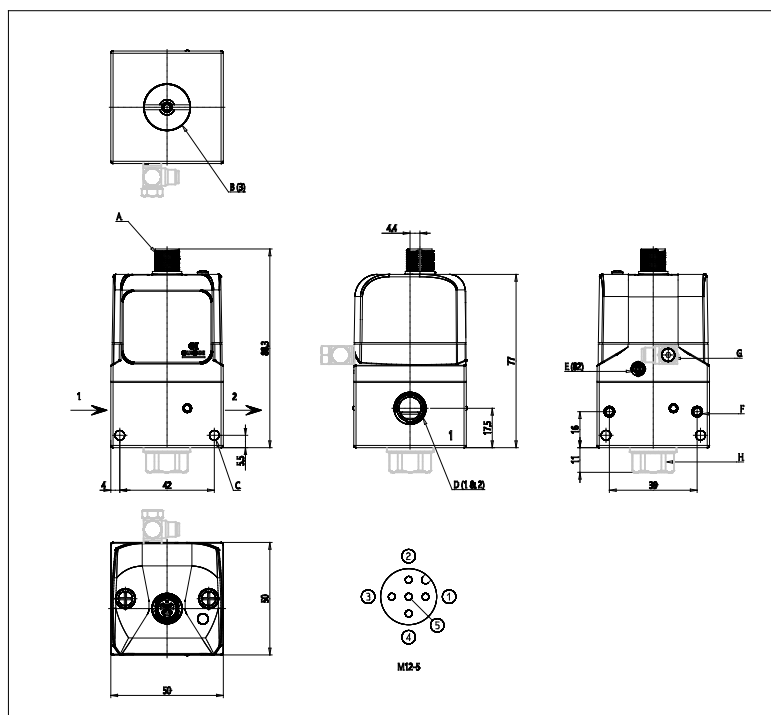

DIMENSIONS

Series	PME
size	1 = Size 1
Connections	08 = G1/8
Diagnostics	E = Without diagnostics and wireless connection
Pressure	D = 0-10,3 bar
Function	5 = Standard, 3-way NC version. with port 3 and pilot exhaust not conveyable
Piloting	I = Internal
Command signal	4 = 4-20 mA
Feedback digital output signal	W = pressure switch with "window" function
Cable length	00 = No cable