

Short-stroke cylinders - Series QL

Product code: QLN2A032A015M

Datasheet creation date: 09/03/2025 23:24

Check the most updated document online [click here](#)




TECHNICAL DATA

| | |
|--------------------------|---|
| Series | QL |
| Version | N = Non magnetic |
| Function | 2 = double - acting |
| Materials | A = rolled stainless steel rod - AL profile |
| Construction type | A = Standard |
| Diameter (mm) | Ø32 |
| Stroke (mm) | 15 |
| Rod | M = Male rod |
| Certification | = Standard |

Short-stroke cylinders - Series QL

Product code: QLN2A032A015M

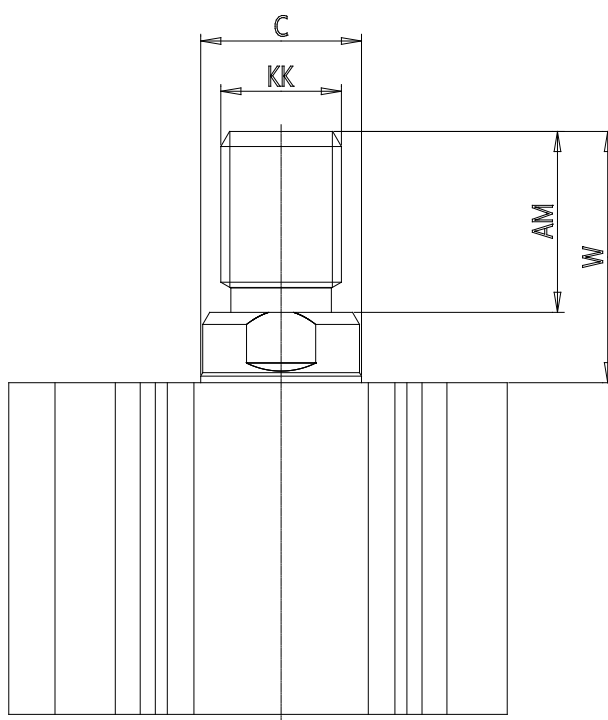

DIMENSIONS

| | |
|---------|---------|
| C (mm) | 16 |
| D (mm) | 49.5 |
| E (mm) | 45.0 |
| G (mm) | 23.0 |
| H (mm) | 10.5 |
| H1 (mm) | 7.5 |
| J | M6x1 |
| K (mm) | 9.0 |
| L (mm) | 7.0 |
| L1 (mm) | 17.0 |
| M (mm) | 13 |
| M1 (mm) | 7.5 |
| N (mm) | 30.0 |
| P | M8x1.25 |
| Q | G1/8 |
| SW (mm) | 14 |
| TG (mm) | 34.0 |
| Z (mm) | 14 |
| W (mm) | 30.5 |
| KK | M14x1.5 |
| AM (mm) | 23.5 |