

## Compact ejectors - Series VEN

Product code: VEN-25NO-I

Datasheet creation date: 10/03/2025 00:26

Check the most updated document online [click here](#)




### TECHNICAL DATA

<b>Series</b>	VEN
<b>Venturi nozzle diameter</b>	25 = 2.5 mm
<b>Valve type</b>	NO = with vacuum at rest position
<b>Version</b>	I = saving of compressed air + I/O LINK

## Compact ejectors - Series VEN

Product code: VEN-25NO-I

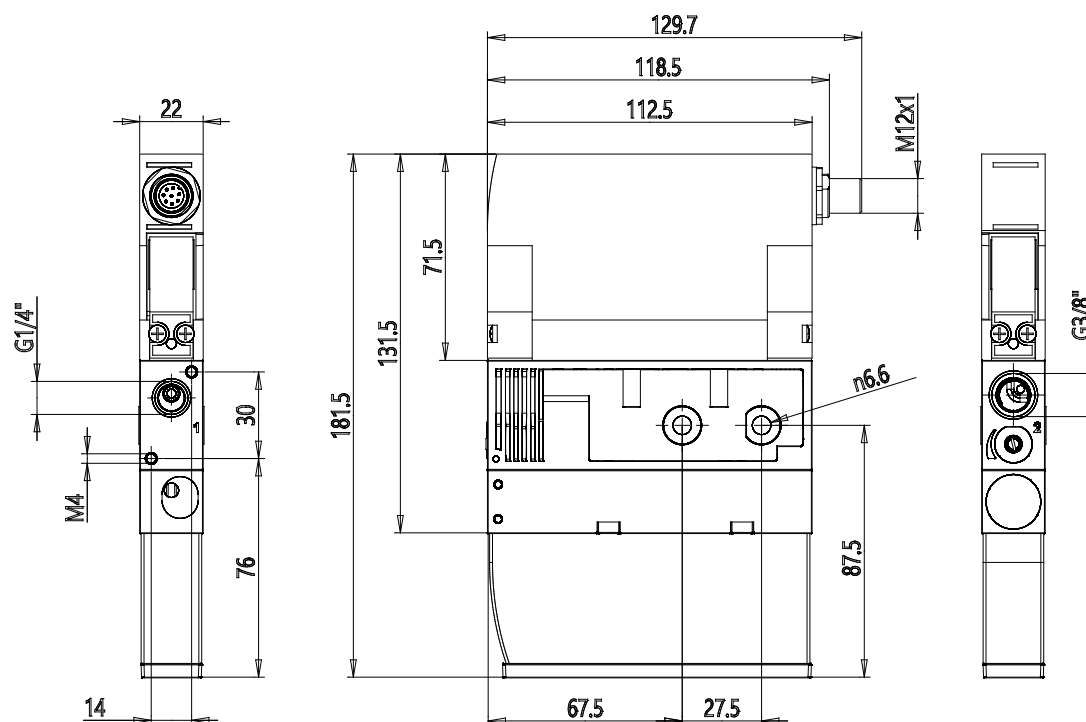

### DIMENSIONS

Nozzle Ø (mm)	2.5
Degree of discharge (%)	85
Max suction capacity ((l/min))	195
Max suction capacity ((m <sup>3</sup> /h))	11.7
Consumption ((l/min))	290
Consumption ((m <sup>3</sup> /h))	17.4
Exhaust consumption ((m <sup>3</sup> /h))	200
Noise in suction ([db(A)])	75
Noise in mantaining ([db(A)])	78
Working pressure (bar)	4 - 7
Int diameter compressed air tube (mm)	8
Int diameter for vacuum tube (mm)	9
Delta temperature (°C)	0 / 50°
L (mm)	93
L1 (mm)	106