

## Direct operated solenoid valves - Series W

Product code: W000-303-W13P

Datasheet creation date: 10/03/2025 11:43

Check the most updated document online [click here](#)




### TECHNICAL DATA

<b>Series</b>	W
<b>Body execution</b>	0 = interface
<b>Number of seats</b>	00 = ISO 15218 interface
<b>Number of ways - Functions</b>	3 = 3/2 way - NC
<b>Valve connections</b>	0 = ISO 15218 interface
<b>Orifice diameter</b>	3 = Ø 1.5 mm
<b>Materials</b>	W = PBT body - NBR - FKM - PU seals
<b>Electrical connection</b>	1 = cables 300 mm
<b>Voltage - Absorbed power</b>	3 = 24 V DC - 2 W
<b>Fixing</b>	P = fixing screws for plastic
<b>Options</b>	= Standard

## Direct operated solenoid valves - Series W

Product code: W000-303-W13P

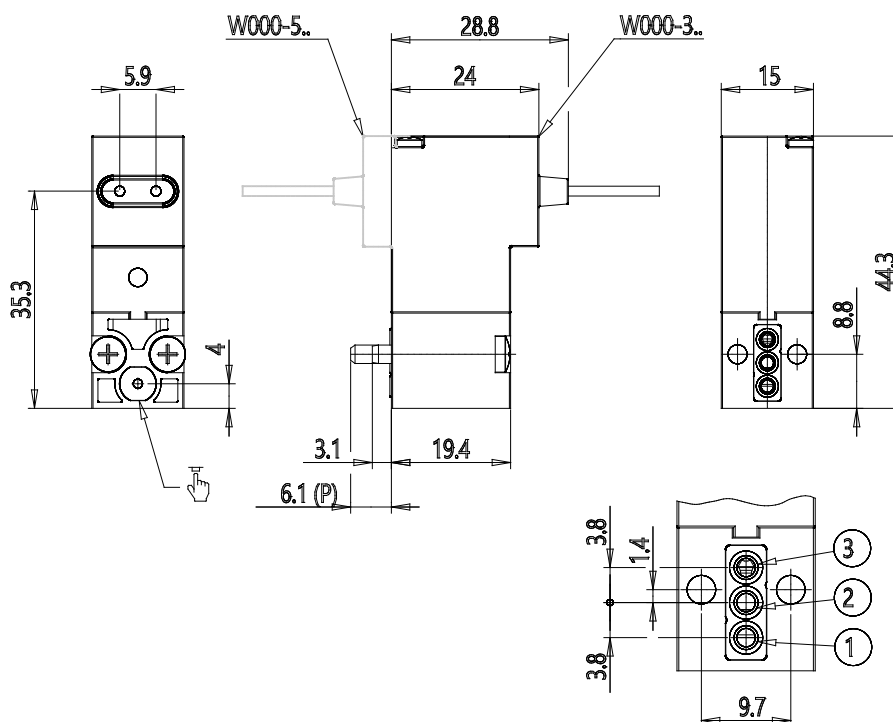

### DIMENSIONS

<b>Series</b>	W
<b>Body execution</b>	0 = interface
<b>Number of seats</b>	00 = ISO 15218 interface
<b>Number of ways - Functions</b>	3 = 3/2 way - NC
<b>Valve connections</b>	0 = ISO 15218 interface
<b>Orifice diameter</b>	3 = $\varnothing$ 1.5 mm
<b>Materials</b>	W = PBT body - NBR - FKM - PU seals
<b>Electrical connection</b>	1 = cables 300 mm
<b>Voltage - Absorbed power</b>	3 = 24 V DC - 2 W
<b>Fixing</b>	P = fixing screws for plastic
<b>Options</b>	= Standard