


Pressostato con scala di taratura visiva Serie PM681-...

Istruzioni operative

Il pressostato chiude un circuito elettrico quando viene raggiunto il valore di pressione impostato.





Made in Italy

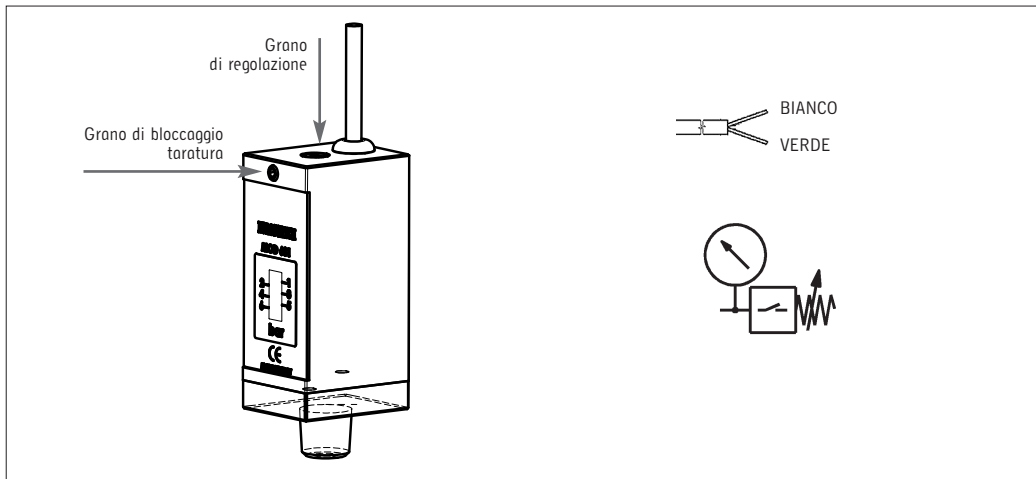

937519-0003 rev.B

⚠ Attenzione!

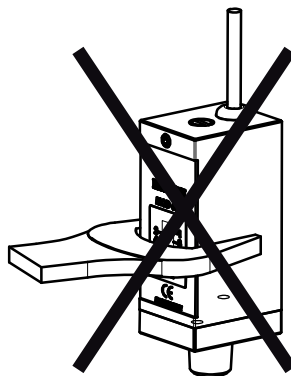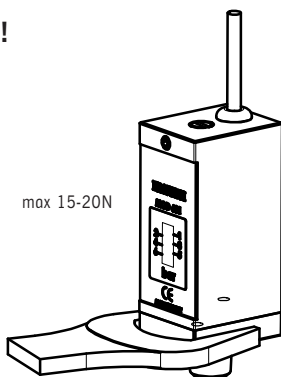

Messa in funzione:



- PM681-... : 2-48V AC/DC; 0,5A; 10W
- IP40
- Campo di regolazione: 1 - 6 bar
- Pressione massima: 20 bar
- Evitare l'impiego in presenza di campi magnetici

- Evitare l'impiego in presenza di gas o fluidi corrosivi
- Non usare in ambienti con acqua e spruzzi d'olio
- Evitare cadute e forti urti
- Evitare una forza eccessiva sui fili elettrici

Pressure switch with setting visual scale Series PM681-...

Operating instructions

The pressure switch close an electrical circuit when the selected pressure value are reach.

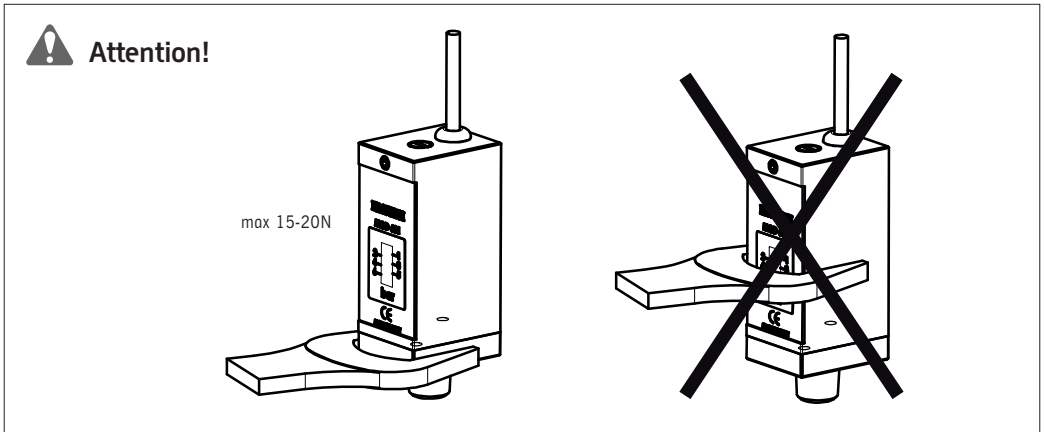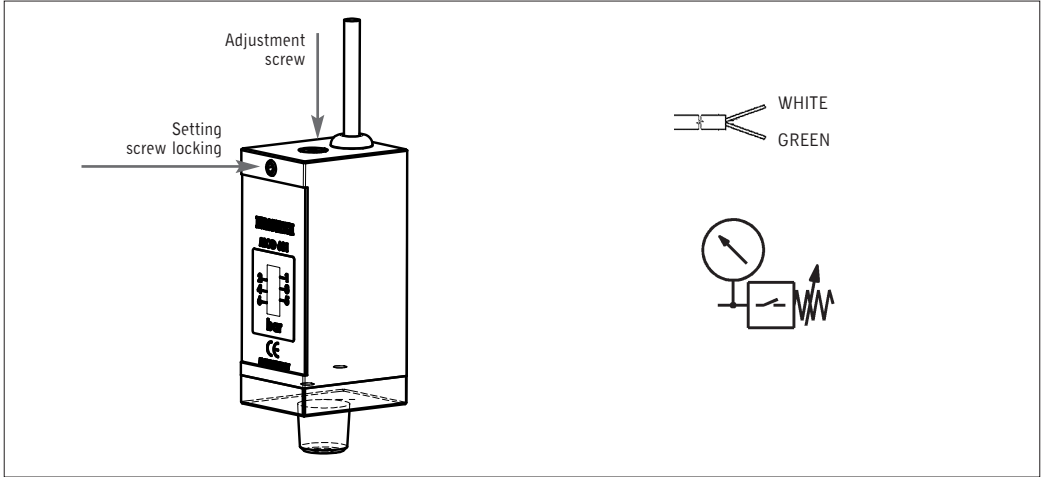

Commissioning:

- PM681-... : 2-48V AC/DC; 0,5A; 10W
- IP40
- Setting range: 1 - 6 bar
- Maximum pressure: 20 bar
- Do not use in magnetic ambient

- Avoid to use with gas and corrosive fluids
- Do not use in water ambient and in presence of drop oil
- Avoid dropping and strong impact
- Avoid excessive force on the wires